




CALL YOUR WOODHEAD REPRESENTATIVE TODAY!

SEE PAGES 2-7



## SAFeway® NYLON DEVICES

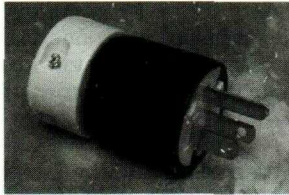

SAFeway® PLUG



SAFeway® 50A PLUG



SAFeway® CONNECTOR

Face View	NEMA Configuration	Amps/Volts	Cord Range	Plug <sup>1</sup>
<b>2-POLE/2-WIRE</b>				
	1-15	15A/125V	.335-.640	5166 / 5176 <sup>6</sup>
	L1-15	15A/125V	.335-.640	24T04
	L2-20	20A/250V	.325-.840	26T07
<b>2-POLE/3-WIRE</b>				
	5-15	15A/125V	.335-.640	5266
	L5-15	15A/125V	.335-.640	4720
	6-15	15A/250V	.335-.640	5666
	L6-15	15A/250V	.335-.640	24T49
	7-15	15A/277V	.335-.640	5766
	L7-15	15A/277V	.335-.640	4770
	5-20	20A/125V	.335-.640	5366
	L5-20	20A/125V	.335-.640	26T47
	6-20	20A/250V	.325-.840	5466
	L6-20	20A/250V	.335-.640	26T48
	L7-20	20A/277V	.325-.840	26T49
	L5-30	30A/125V	.325-.840	28T47
	L6-30	30A/250V	.425-1.150	28T48
	L7-30	30A/277V	.425-1.150	28T49
<b>2-POLE/3-WIRE GROUNDING, LOCKING, NON-NEMA, CALIFORNIA STYLE</b>				
	Non-NEMA Locking	50A/125V		CS6361N
	Non-NEMA Locking	50A/250V		CS8265N
	Non-NEMA Locking	50A/480V		CS8465N
<b>2-POLE/3-WIRE, GROUNDING, LOCKING, NON-NEMA, STANDARD DUTY</b>				
	Non-NEMA Locking	50A/125V		6361CRN
	Non-NEMA Locking	50A/250VDC/600VAC		3763N

<sup>1</sup> To order Safeway® devices in yellow, add "YL" suffix to Woodhead number.

For dimensional information, see pages 147-149.

<sup>2</sup> Standard color is brown.

<sup>3</sup> Standard color is black.

<sup>4</sup> For corrosion-resistant receptacle, add "CR" suffix to part number (e.g., 4949CR).

<sup>5</sup> For complete listing of receptacles, see pages 150-151.

<sup>6</sup> Polarized