




CALL YOUR WOODHEAD REPRESENTATIVE TODAY!

SEE PAGES 2-7




WATERTITE® RUBBER DEVICES

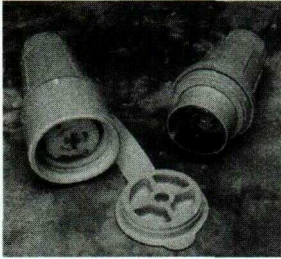

WATERTITE® 50A PLUG AND CONNECTOR



WATERTITE® PLUG

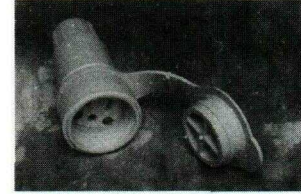

WATERTITE® CONNECTOR

Face View	NEMA Configuration	Amps/ Volts	Plug ¹	Connector ¹	Single Coverplate With Female Receptacle
3-POLE/4-WIRE					
	L14-20	20A/125V/250V	26W74	27W74	67W74
	L15-20	20A/3ø/250V	26W75	27W75	67W75
	L16-20	20A/3ø/480V	26W76	27W76	67W76
	L14-30	30A/125V/250V	28W74	29W74	69W74
	L15-30	30A/3ø/250V	28W75	29W75	69W75
	L16-30	30A/3ø/480V	28W76	29W76	69W76
	L17-30	30A/3ø/600V	28W77	29W77	69W77
	Non-NEMA Locking	50A/125V/250V	CS63W65	CS63W64	CS60W64³
	Non-NEMA Locking	50A/125V/250V	63W65	63W64	60W64³
	Non-NEMA Locking	50A/250V/3ø	CS83W65	CS83W64	65W64³
	Non-NEMA Locking	50A/250VDC/600VAC	37W65	37W64	66W64³
	Non-NEMA Locking	50A/480V/3ø	CS81W65	CS81W64	64W64³

¹ For cable range and proper cord specifications, see pages 168-170.

³ 50 Amp receptacles have weather resistant enclosures only.

For dimensional information, see pages 117-118.

For extra-hard outdoor use, order Watertite® devices in UV resistant black, add "BLK" to the end of the Woodhead number.