

Nylon Standard Strain Relief Fitting M12 x 1.5



Nylon Standard Strain Relief Fitting M12 X 1.5

Thread Range: M12 x 1.5

Locking Nut & O-Ring Sold Separately

Sealcon # CD12MA-BK
Type .12" - .26" (3 - 6.5 mm)
Color **Black**

Hummel # 1.209.1201.50
Hummel **HSK-K**
Material **Nylon**

Hole Diameter (A) | .47" (12 mm)


Body Length (B) | .83" (21 mm)

Thread Length (D) | .31" (8 mm)

Wrench Flat (F1/F) | .59" (15 mm)



Suggested Clearance Hole for Non-Threaded Mounting

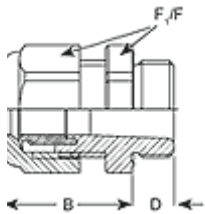

Technical Data

Materials

Fittings: Nylon 6/6

Form Seal: Buna-N

Optional O-Ring: Buna-N, FPM© or Silicone

Optional Seal Ring: Polyethylene or Fiber-Reinforced Plastic

Protection

IP 68 – 10 bar / IP 69K within the specific clamping range only with optional O-Ring (see page 144)

Operating Temperature

-40°C to 100°C (-40°F to 212°F)

Available Colors








Black (RAL 9005)

Gray (RAL 7035)

Blue (RAL 5012) - upon request

Nylon 6/6: V0-rated - Flame resistant, halogen and phosphorous free, self-extinguishing, non-toxic, fungus resistant.

Approvals

-  RoHS Compliance
-  Deca Bde Deca-Bromo-Diphenyl-Ether Compliance
-  Registration, Evaluation, Authorization and Restriction of Chemicals
-  Waste Electrical and Electronic Equipment Directive
-  cULus
-  Listed Underwriters Laboratories
-  Canadian Standard Association
-  EAC
-  Registered Underwriters Laboratories
-  Certified European Approval
-  German Lloyd
-  Association of German Electrical Engineers
-  V0 UL94 Rated / Approved