




CATALOG NUMBER: See table below
DESCRIPTION: POLAR/SOLAR® extension cord with power indicator light in the cord connector
APPROVALS: UL Listed and CSA Certified (16-12 ga) Outdoor Use Cord Set

CONSTRUCTION PARAMETERS:

Cable type: SJEOOW, see table below for gauge
 Cable jacket material: TPE, yellow
 Cord rating: Hard Usage per the National Electrical Code
 Cable legend type: Indent print

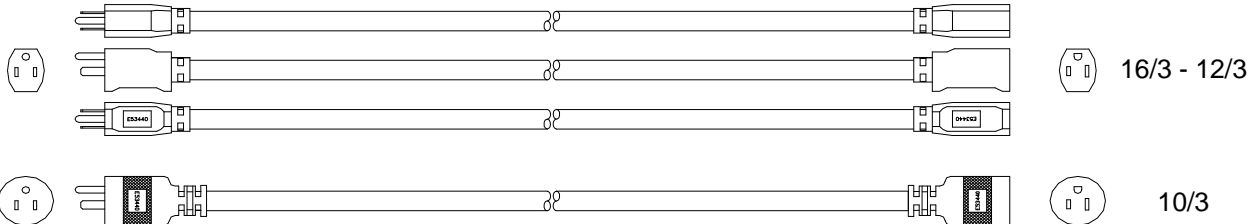

Attachment plug configuration: NEMA 5-15P
 Cord connector configuration: NEMA 5-15R
 Plug and connector material: Clear PVC, with neon power indicator lamp in the connector

ELECTRICAL AND ENVIRONMENTAL PROPERTIES:

Cable temperature rating: -50 to +105 °C
 Nominal operating voltage: 125 VAC
 Maximum operating current: See table below

Catalog no.	Gauge	Length	Current rating	Case qty	UPC
12870002	16/3	25 ft	13A	12	0 29892 01287 8
12880002		50 ft		12	0 29892 01288 5
12890002		100 ft	10A	6	0 29892 01289 2
14840002	14/3	10 ft	15A	24	0 29892 01484 1
14870002		25 ft		12	0 29892 01487 2
14880002		50 ft		6	0 29892 01488 9
14890002		100 ft		13A	6
16870002	12/3	25 ft	15A	12	0 29892 01687 6
16880002		50 ft		6	0 29892 01688 3
16890002		100 ft		4	0 29892 01689 0
17870002	10/3	25 ft		6	0 29892 01787 3
17880002		50 ft		4	0 29892 01788 0
17890002		100 ft		3	0 29892 01789 7

This product complies with European Directive 2011/65/EU (RoHS-2)

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part.

We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is the proprietary intellectual property of Southwire Company LLC. Any information contained herein shall not be disclosed to any party without the written consent of Southwire Company LLC.