

## DESCRIPTION

This Universal Lampholder family from Halo provides a broad range of clean, stylish lighting. The specialized accessories make possible a customized lighting effect and lampholder look. Lampholders are offered in a symmetrical and an asymmetrical version. For use with Halo and Lazer-by-Halo track systems.


Catalog #	Type
Project	
Comments	
Prepared by	Date

## SPECIFICATION FEATURES

### A...Electrical Quick Lock Adapter

Polycarbonate casing. Attaches electrically and mechanically anywhere along Power-Trac. Visual polarity line assures proper grounding. Two position conductor allows use in single circuit and either circuit of two circuit track.

L1701

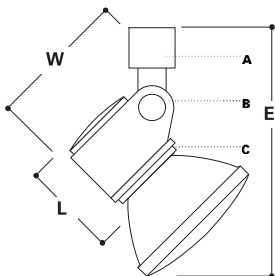

### B...Stem/ Arm

Stem/arm allows lampholder to rotate 338° and adjust vertically from 0° to 90°.


### C...Body

Body is polycarbonate construction in white or black textured finish.

### Listings


UL listed and CSA certified for use with Halo and Lazer-by-Halo track and track systems.

L1702

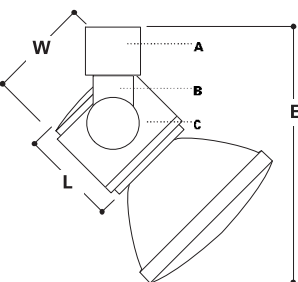


### ACCESSORIES


L281 Perforated Shade

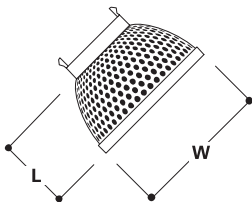


L282 Perforated Shade

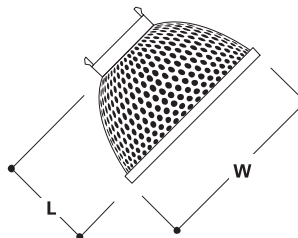


L283 Polymer Light Shield

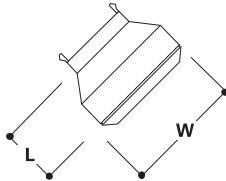

L284 Polymer Light Shield

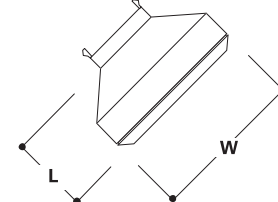

L298 Bellows

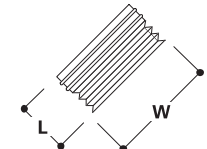

L1701

L1702

LINE VOLTAGE  
UNIVERSAL  
LAMPHOLDERS  
Power-Trac®

## ORDERING INFORMATION

SAMPLE NUMBER: L1701P

Lampholders	Finishes	Accessories	Finishes
L1701 L1702	P=Satin White MB=Matte Black	L281 L282 L283 L284 L298	P=Satin White (except L298 Bellows) MB=Matte Black

### L1701

For use with:  
55W PAR16, 50W PAR20,  
75W PAR30, 150W PAR38  
L =2 7/16" [62mm]  
W=2 1/2" [64mm]  
E =5 3/8" [137mm]

### L1702

For use with:  
55W PAR16, 50W PAR20,  
75W PAR30, 150W PAR38  
L =2 7/16" [62mm]  
W=2 1/2" [64mm]  
E =4" [102mm]

### Accessories

L281 Perforated Shade  
L=1 13/16" [46mm]  
W=3 3/4" [95mm]  
L282 Perforated Shade  
L=2 1/2" [64mm]  
W=5" [127mm]

L283 Light Shield  
L=1 5/8" [41mm]  
W=3 1/8" [79mm]  
L284 Light Shield  
L=2 1/8" [54mm]  
W=4 3/8" [111mm]  
L298 Bellows  
L=7/8" [22mm]  
W=2 3/16" [56mm]

Note: Specifications and Dimensions subject to change without notice.

ADV990347

Visit our web site at [www.cooperlighting.com](http://www.cooperlighting.com)