

DESCRIPTION

Lampholder utilizes 12V MR16 lamps and provides a very white crisp light. Lampholders are available in Satin White or Matte Black finishes. Lazer lampholders are compatible with all Halo Power-Trac systems (except 4-circuit Trac).

Catalog #	Type
Project	
Comments	
Prepared by	Date

SPECIFICATION FEATURES

A...Electrical Quick Lock Adapter/Transformer

Lexan polycarbonate casing. Attaches electrically and mechanically anywhere along the track. Visual polarity line assures proper grounding. Two position conductor allows use in single circuit and either circuit of two circuit track. All solid-state components lower 120V line voltage down to lamp operating voltage

B...Arm

Matching finish sculpted arm allows lampholder to rotate 338°.

C...Rotation Assembly

Adjustable rotation assembly allows lampholder to rotate from 0° to 90°.

D...Lens/Lamp Holder

Cover glass (included) is held in position with three molded retainer stubs. Lampholder will

accept any 2" diameter UV, color filter or lens. Lamp is secured with spring.

E...Button

Grey button provides a "handle" for adjusting swivel and rotation of lampholder.

Listings

UL/CSA listed for use with Halo and Lazer-by-Halo track and track systems




LZR404

**LINE VOLTAGE
FLAT PENDANT STYLE
LAMPHOLDER**

Lazer by Halo

ENERGY DATA

Power Factor: >.90
Input Watts: <50
Input Amps: .45 Max.
THD: <30%

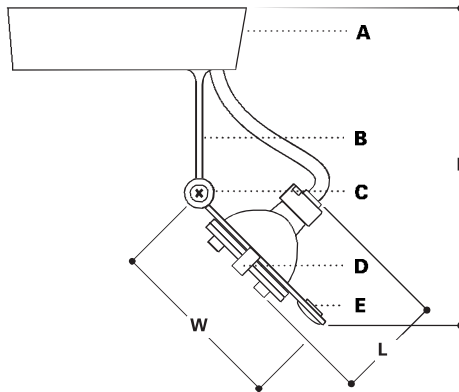

ORDERING INFORMATION

 
SAMPLE NUMBER: LZR404P

Lampholders

LZR404=Pendant

Finishes

P=Satin White
MB=Satin Black



LZR404

For use with:
50W Max. 12V MR16

W=3" [76mm]
L =2" [51mm]
E =7" [178mm]

ADV990376

9/04

TAB: Lazer Lampholders and Track
Sheet 11

Note: Specifications and Dimensions subject to change without notice.

Visit our web site at www.cooperlighting.com