




LAZER TRACK

FEATURES

- Accepts both Lazer Track and Power-Trac luminaires
- Structural channel is extruded aluminum
- Conductors are solid copper encased in rigid extruded PVC insulators
- Visual polarity indicates proper electrical installation of fixtures
- Track comes in 2', 4', 6' and 8' lengths
- Finishes: White (P) and Black (MB)

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL Listed, CSA Listed

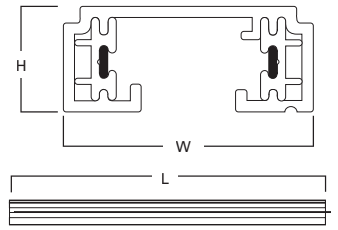

	L	W	H
LZR102 2' Nominal	20-1/8" [511mm]	1-3/8" [35mm]	5/8" [14mm]
LZR104 4' Nominal	44-1/8" [1121mm]	1-3/8" [35mm]	5/8" [14mm]
LZR106 6' Nominal	68-1/8" [1730mm]	1-3/8" [35mm]	5/8" [14mm]
LZR108 8' Nominal	92-1/8" [2340mm]	1-3/8" [35mm]	5/8" [14mm]

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY

SAMPLE NUMBER: LZR102P

Track	Finishes	Connectors (Order Separately)	Accessories (Order Separately)	Current Limiters (Order Separately)
LZR102 =2' Lazer Miniature Single Circuit Track System LZR104 =4' Lazer Miniature Single Circuit Track System LZR106 =6' Lazer Miniature Single Circuit Track System LZR108 =8' Lazer Miniature Single Circuit Track System	MB =Black P =White	LZR200 =Live End Feed with Junction Box Cover LZR201 =Live End Feed LZR202 =Floating Canopy and Connector LZR203 =Adjustable L and Straight Connector LZR204 =Conduit Adapter Feed LZR205 =Conduit Continuation Feed LZR206 =T-Bar Canopy LZR208 =Cord and Plug Feed LZR211 =Flexible Connector Feed LZR212 =Mini Joiner LZR213L = "T" Connector - Left LZR213R = "T" Connector - Right LZR214 = "X" Connector Finishes MB =Black P =White	LZR207 =T-Bar Mounting Clip LZR209 =Monopoint Feed LZR210 =Monopoint Feed-Low Voltage Finishes MB =Black P =White	Current Limiter-Center Feed LZRC203CB120 =120W (1A@120V) LZRC203CB1200 =1200W (10A@120V) LZRC203CB300 =300W (2.5A@120V) LZRC203CB600 =600W (5A@120V) LZRC203CB960 =960W (8A@120V) Current Limiter-End Feed LZRC201CB120 =120W (1A@120V) LZRC201CB1200 =1200W (10A@120V) LZRC201CB300 =300W (2.5A@120V) LZRC201CB600 =600W (5A@120V) LZRC201CB960 =960W (8A@120V) Finishes MB =Black P =White

CONNECTORS AND ACCESSORIES



LZR200 Live End Feed with Junction Box Cover



LZR201 Live End Feed



LZR202 Floating Canopy and Connector Feed



LZR203 Adjustable L and Straight Connector Feed



LZR204 Conduit Adapter Feed



LZR205 Conduit Continuation Feed



LZR206 T-Bar Canopy



LZR207 T-Bar Mounting Clip



LZR208 Cord and Plug Feed



LZR209 Monopoint Feed



LZR210 Monopoint Feed - Low Voltage



LZR211 Flexible Connector Feed



LZR212 Mini Connector



LZR213R Right Handed "T" Connector



LZR213L Left Handed "T" Connector



LZR214 "X" Connector



DE112 Dead End



LZRC201, LZRC203 Current Limiters

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.