


BKOC Series Commercial Baseboard Heaters



DIMENSIONS

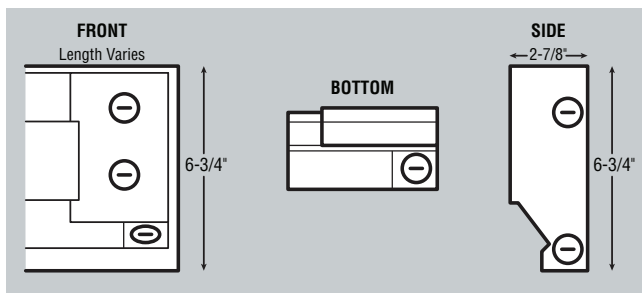

All knockouts are 7/8" diameter for 1/2" conduit



▶ **APPLICATIONS:**

THE BKOC, WITH ITS COMPLETE LINE OF ACCESSORIES AND CONTROLS, CAN SOLVE THE SPACE HEATING NEEDS OF VIRTUALLY ANY TYPE COMMERCIAL STRUCTURE. INDIVIDUAL ROOM CONTROL ALLOWS YOU TO HEAT EACH ROOM SEPARATELY FOR UTMOST ENERGY SAVINGS.

▶ **COMMERCIAL GRADE CONSTRUCTION**

– 18-GAUGE FRONT COVER AND BRACKETS ALLOW HEATER TO WITHSTAND RIGORS OF COMMERCIAL APPLICATIONS

▶ **BUILT-IN WIREWAY**

– FACILITATES END-TO-END INSTALLATION OF CONTINUOUS-RUN HEATERS

▶ **EFFICIENT HEAT DISSIPATION**

– “CHIMNEY FIN” TYPE ELEMENT DESIGNED FOR MAXIMUM AIR CIRCULATION. AIR FLOW IS DIRECTED AWAY FROM WALLS

▶ **STEEL SHEATHED ELEMENT**

– HEATING ELEMENT DESIGN COMBINES THE DURABILITY OF A STEEL TUBULAR HEATER WITH THE EXCELLENT HEAT TRANSFER CHARACTERISTICS OF ALUMINUM FINNS

▶ **ROOMY JUNCTION BOX**

– LARGE, IDENTICAL, PRE-WIRED JUNCTION BOXES AT EACH END ARE PROVIDED WITH KNOCKOUTS IN THE REAR, BOTTOM, INSIDE AND OUTSIDE JUNCTION BOX WALLS.



SELECTION CHART

CATALOG NUMBER	VOLTS	WATTS	BTU/HR	AMPS	LENGTH	WT. (LBS.)
BKOC25126W	120	500	1706	4.2	2'6"	7.8
BKOC25026W	208	500	1706	2.4		
BKOC25426W	240/208	500/376	1706/1283	2.1/1.8		
BKOC25726W	277/240/208	500/376/282	1706/1283/962	1.8/1.6/1.4		
BKOC2513W	120	750	2560	6.3	3'	9.0
BKOC2503W	208	750	2560	3.6		
BKOC2543W	240/208	750/564	2560/1925	3.1/2.7		
BKOC2573W	277/240/208	750/564/423	2560/1925/1443	2.7/2.4/2.0		
BKOC2514W	120	1000	3413	8.3	4'	11.5
BKOC2504W	208	1000	3413	4.8		
BKOC2544W	240/208	1000/752	3413/2567	4.2/3.6		
BKOC2574W	277/240/208	1000/752/564	3413/2567/1925	3.6/3.1/2.7		
BKOC2515W	120	1250	4266	10.4	5'	13.0
BKOC2505W	208	1250	4266	6.0		
BKOC2545W	240/208	1250/940	4266/3208	5.2/4.5		
BKOC2575W	277/240/208	1250/940/705	4266/3208/2405	4.5/3.9/3.4		
BKOC2516W	120	1500	5120	12.5	6'	15.5
BKOC2506W	208	1500	5120	7.2		
BKOC2546W	240/208	1500/1128	5120/3850	6.3/5.4		
BKOC2576W	277/240/208	1500/1128/846	5120/3850/2887	5.4/4.7/4.1		
BKOC2508W	208	2000	6826	9.6	8'	20.0
BKOC2548W	240/208	2000/1504	6826/5133	8.3/7.2		
BKOC2578W	277/240/208	2000/1504/1128	6826/5133/3850	7.2/6.3/5.4		
BKOC25008W	208	2500	8533	12.0		
BKOC25408W	240/208	2500/1880	8533/6416	10.4/9.0	8'	20.0
BKOC25708W	277/240/208	2500/1880/1410	8533/6416/4811	9.0/7.8/6.		


Accessories

CATALOG NUMBER	DESCRIPTION	CASE QTY.	SHIP WEIGHT (lbs.)
TA1AW	SP Thermostat, rated 22A @ 120-277V, 15A @ 347V, 10A @ 600V	1	1
TA1TPAW	Tamper resistant version of above.	1	1
TA2AW	DP Thermostat, rated 22A @ 120-277V 15.5A @ 347V, 10A @ 600V	1	1
TA2TPAW	Tamper resistant version of above.	1	1
HCA121520W	120V Load Transfer Switch.	1	1
HCA241520W	240V Load Transfer Switch.	1	1
RA1W	120V Duplex Receptacle	1	1
RA1COMPW	Duplex Receptacle Cover Only. (carton of 10)	10	3
DSW2W	Double Pole Disconnect Switch Rated 20A @ 120-277V	1	1
PR24	Single Pole Power Relay 24V Control Rated 30A @ 120-240V 23A @ 277V, 10A @ 347V	1	1
PR120	Same as above except 120V Control.	1	1
RSA1224	120/24V Transformer Relay - 25A	1	1
RSA2024	208/24V Transformer Relay - 25A	1	1
RSA2424	240/24V Transformer Relay - 25A	1	1
RSA2724	277/24V Transformer Relay - 25A	1	1
ICAW	Inside Corner.	1	1

Filler Sections

CATALOG NUMBER	DESCRIPTION	CASE QTY.	SHIP WEIGHT (lbs.)
BKOCBDA2W	2' 6" Blank Section	1	3
BKOCBDA3W	3' Blank Section	1	4
BKOCBDA4W	4' Blank Section	1	6
BKOCBDA5W	5' Blank Section	1	8
BKOCBDA6W	6' Blank Section	1	10
BKOCBDA8W	8' Blank Section	1	13

FEATURES

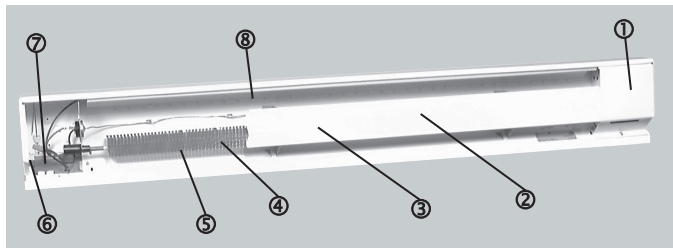

- ① Large wiring compartment and accessible grounding pigtail. Completely pre-wired at both ends
- ② 18 ga. Front Cover and 18 ga. Front Cover support brackets
- ③ Navajo White durable textured polyester powder coat finish
- ④ "Chimney-fin" type element moves air at greater velocity and results in less wall streaking
- ⑤ Suspended heating element designed to lower noise of heater when warming up
- ⑥ "Easy-out" knockouts at each end of heater facilitates fast and easy wire entry and exit from wiring compartments.
- ⑦ Built-in Back entry cable clamp provides access to wiring compartment from rear for fast wiring
- ⑧ Pre-notched guide marks for fast installation.