

PROLINE G2 SOLID TOP



APPLICATION

PROLINE G2 Solid tops are used to close the top opening on an enclosure frame.

FEATURES

- Lifting eyes can be used to attach the solid top, in place of the included hardware
- Seamless polyurethane gasket (UL listed) provides a water-tight, dust-tight seal against moisture and contaminants

SPECIFICATIONS

- 16 gauge (1.5 mm) steel
- Additional support provisions need to be made to support top mount air conditioners or other top mount accessories
- Includes four M12 hex bolts for installation

EMC Solid Tops – Additional Specifications:

- Plated to provide corrosion resistance while maintaining a metal to metal contact with the metal fiber gasket
- Metalized non-woven fabric EMI/RFI material covering UL94HP rated urethane foam gasket
- Plating exposed in interior and paint over plated exterior

FINISH

- Polyester powder paint; RAL 7035 textured light gray standard
- Dip coated primed
- Custom colors available


ACCESSORIES

- Lifting eyes
- Lifting angles
- Lifting bar
- Support Bracket Kit
- Grid Strap (to form internal grid network/rail system)
- Hole Seal

BULLETIN: P40

Standard Product

| Catalog Number | W (mm) | W (in.) | D (mm) | D (in.) | Gauge | Fits Frame WxD | Description |
|----------------|--------|---------|--------|---------|-------|----------------|-------------|
| P2T45 | 379 | 14.9 | 459 | 18.1 | 16 | 400x500 | Painted |
| P2T46 | 379 | 14.9 | 559 | 22.0 | 16 | 400x600 | Painted |
| P2T64 | 579 | 22.8 | 359 | 14.1 | 16 | 600x400 | Painted |
| P2T65 | 579 | 22.8 | 459 | 18.1 | 16 | 600x500 | Painted |
| P2T66 | 579 | 22.8 | 559 | 22.0 | 16 | 600x600 | Painted |
| P2T66HF | 579 | 22.8 | 559 | 22.0 | 16 | 600x600 | EMC |
| P2T68 | 579 | 22.8 | 759 | 29.9 | 16 | 600x800 | Painted |
| P2T84 | 779 | 30.7 | 359 | 14.1 | 16 | 800x400 | Painted |
| P2T85 | 779 | 30.7 | 459 | 18.1 | 16 | 800x500 | Painted |
| P2T86 | 779 | 30.7 | 559 | 22.0 | 16 | 800x600 | Painted |
| P2T86HF | 779 | 30.7 | 559 | 22.0 | 16 | 800x600 | EMC |
| P2T88 | 779 | 30.7 | 759 | 29.9 | 16 | 800x800 | Painted |
| P2T810 | 779 | 30.7 | 959 | 37.8 | 16 | 800x1000 | Painted |
| P2T104 | 979 | 38.5 | 359 | 14.1 | 16 | 1000x400 | Painted |
| P2T105 | 979 | 38.5 | 459 | 18.1 | 16 | 1000x500 | Painted |
| P2T106 | 979 | 38.5 | 559 | 22.0 | 16 | 1000x600 | Painted |
| P2T106HF | 979 | 38.5 | 559 | 22.0 | 16 | 1000x600 | EMC |
| P2T108 | 979 | 38.5 | 759 | 29.9 | 16 | 1000x800 | Painted |
| P2T124 | 1179 | 46.4 | 359 | 14.1 | 16 | 1200x400 | Painted |
| P2T125 | 1179 | 46.4 | 459 | 18.1 | 16 | 1200x500 | Painted |
| P2T126 | 1179 | 46.4 | 559 | 22.0 | 16 | 1200x600 | Painted |
| P2T128 | 1179 | 46.4 | 759 | 29.9 | 16 | 1200x800 | Painted |
| P2T164 | 1579 | 62.2 | 359 | 14.1 | 16 | 1600x400 | Painted |
| P2T165 | 1579 | 62.2 | 459 | 18.1 | 16 | 1600x500 | Painted |
| P2T166 | 1579 | 62.2 | 559 | 22.0 | 16 | 1600x600 | Painted |
| P2T168 | 1579 | 62.2 | 759 | 29.9 | 16 | 1600x800 | Painted |
| P2T185 | 1779 | 70.0 | 459 | 18.1 | 16 | 1800x500 | Painted |
| P2T186 | 1779 | 70.0 | 559 | 22.0 | 16 | 1800x600 | Painted |
| P2T188 | 1779 | 70.0 | 759 | 29.9 | 16 | 1800x800 | Painted |

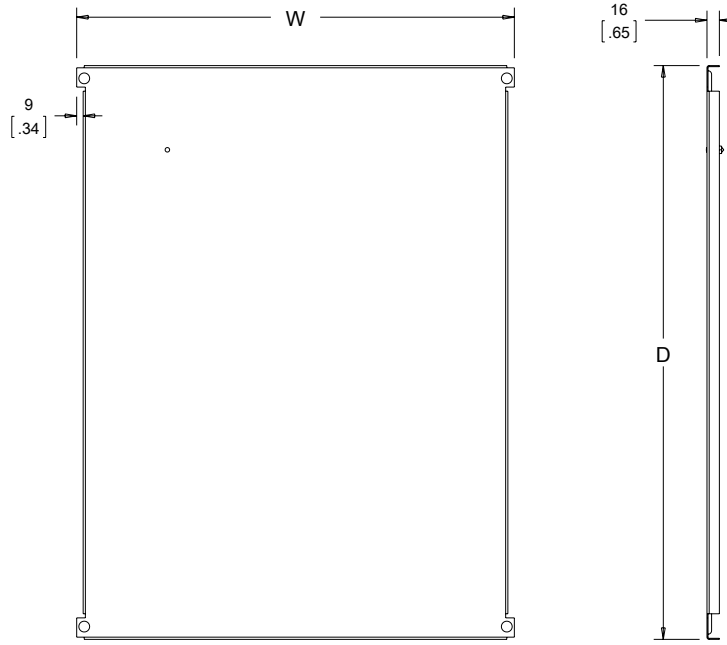

89129482

| Model | Component | Type | Width | Depth | Specialty | Catalog Number |
|------------|-----------|--|--|---|--|----------------|
| P2 | T | Blank | 8 | 6 | Blank | = P2T86 |
| PROLINE G2 | Top | Blank = solid top P = pagoda top PH = top with cutout for high-performance pagoda vent | mm 18 = 1800 16 = 1600 14 = 1400 12 = 1200 10 = 1000 8 = 800 6 = 600 4 = 400 | mm 10 = 1000 8 = 800 6 = 600 5 = 500 4 = 400 | Blank = standard HF = EMC protected | |