

PROLINE G2 PARTIAL SUBPANEL



APPLICATION

Partial Subpanels can be used on the sides of a modular enclosure or placed at any depth in 25-mm increments.

FEATURES

- 12 gauge (2.5mm), mild steel or galvanized steel
- Flanges on all four sides

SPECIFICATIONS

- Partial subpanels can be placed in the rearmost position of the enclosure at any vertical height in 25-mm increments, or placed at any depth using grid straps (not included)
- Side-mount partial subpanels can be placed on either side at any vertical height in 25-mm increments.
- All necessary mounting hardware is included

FINISH


- Painted polyester powder paint; white
- Dip coated primed
- Custom colors available

BULLETIN: P40

Standard Product Front- or Rear-Mount Partial Subpanels

Catalog Number	Nominal H (mm)	Nominal H (in.)	Nominal W (mm)	Nominal W (in.)
P2PP54	500	19.69	400	15.75
P2PP54G	500	19.69	400	15.75
P2PP56	500	19.69	600	23.62
P2PP56G	500	19.69	600	23.62
P2PP58	500	19.69	800	31.50
P2PP58G	500	19.69	800	31.50
P2PP510	500	19.69	1000	39.38
P2PP510G	500	19.69	1000	39.38
P2PP512	500	19.69	1200	47.24
P2PP512G	500	19.69	1200	47.24
P2PP74	700	27.56	400	15.75
P2PP74G	700	27.56	400	15.75
P2PP76	700	27.56	600	23.62
P2PP76G	700	27.56	600	23.62
P2PP78	700	27.56	800	31.50
P2PP78G	700	27.56	800	31.50
P2PP710	700	27.56	1000	39.38
P2PP710G	700	27.56	1000	39.38
P2PP712	700	27.56	1200	47.24
P2PP712G	700	27.56	1200	47.24
P2PP94	900	35.43	400	15.75
P2PP94G	900	35.43	400	15.75
P2PP96	900	35.43	600	23.62
P2PP96G	900	35.43	600	23.62
P2PP98	900	35.43	800	31.50
P2PP98G	900	35.43	800	31.50
P2PP910	900	35.43	1000	39.38
P2PP910G	900	35.43	1000	39.38
P2PP912	900	35.43	1200	47.24
P2PP912G	900	35.43	1200	47.24
P2PP114	1100	43.31	400	15.75
P2PP114G	1100	43.31	400	15.75
P2PP116	1100	43.31	600	23.62
P2PP116G	1100	43.31	600	23.62
P2PP118	1100	43.31	800	31.50
P2PP118G	1100	43.31	800	31.50
P2PP1110	1100	43.31	1000	39.38
P2PP1110G	1100	43.31	1000	39.38
P2PP1112	1100	43.31	1200	47.24
P2PP1112G	1100	43.31	1200	47.24


Model	Component	Type	Height	Width	Specialty	Catalog Number
P2	P	P	9	8	G	= P2PP98G
PROLINE G2	Mounting Subpanel	Blank = full subpanel SM = full, side-mount J = joining P = partial PSM = partial, side-mount SO = swing-out	mm 11 = 1100 9 = 900 7 = 700 5 = 500	mm 12 = 1200 10 = 1000 8 = 800 6 = 600 4 = 400	Blank = painted G = galvanized	

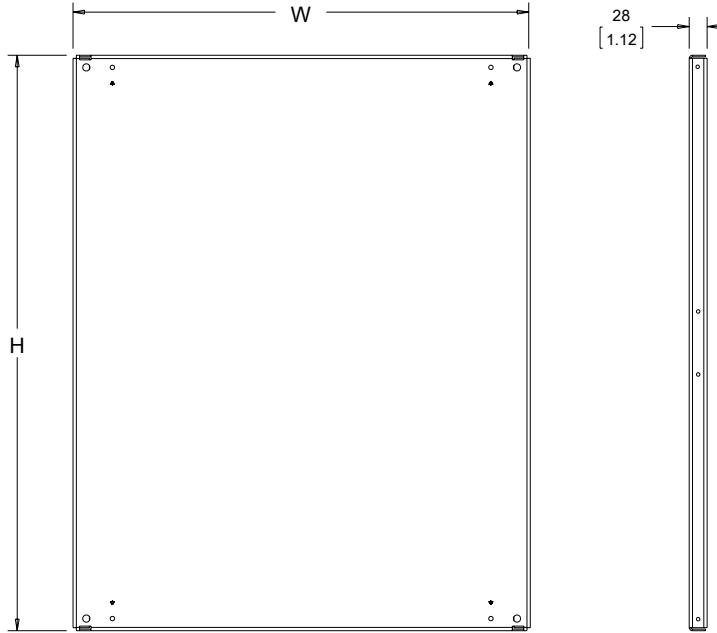

89129502

Standard Product **Side-Mount Partial Subpanels**

Catalog Number	Nominal H (mm)	Nominal H (in.)	Nominal D (mm)	Nominal D (in.)
P2PPSM54	500	19.69	400	15.75
P2PPSM54G	500	19.69	400	15.75
P2PPSM55	500	19.69	500	19.69
P2PPSM55G	500	19.69	500	19.69
P2PPSM56	500	19.69	600	23.62
P2PPSM56G	500	19.69	600	23.62
P2PPSM58	500	19.69	800	31.50
P2PPSM58G	500	19.69	800	31.50
P2PPSM510	500	19.69	1000	39.37
P2PPSM510G	500	19.69	1000	39.37
P2PPSM74	700	27.56	400	15.75
P2PPSM74G	700	27.56	400	15.75
P2PPSM75	700	27.56	500	19.69
P2PPSM75G	700	27.56	500	19.69
P2PPSM76	700	27.56	600	23.62
P2PPSM76G	700	27.56	600	23.62
P2PPSM78	700	27.56	800	31.50
P2PPSM78G	700	27.56	800	31.50
P2PPSM710	700	27.56	1000	39.37
P2PPSM710G	700	27.56	1000	39.37
P2PPSM94	900	35.43	400	15.75
P2PPSM94G	900	35.43	400	15.75
P2PPSM95	900	35.43	500	19.69
P2PPSM95G	900	35.43	500	19.69
P2PPSM96	900	35.43	600	23.62
P2PPSM96G	900	35.43	600	23.62
P2PPSM98	900	35.43	800	31.50
P2PPSM98G	900	35.43	800	31.50
P2PPSM910	900	35.43	1000	39.37
P2PPSM910G	900	35.43	1000	39.37
P2PPSM114	1100	43.31	400	15.75
P2PPSM114G	1100	43.31	400	15.75
P2PPSM115	1100	43.31	500	19.69
P2PPSM115G	1100	43.31	500	19.69
P2PPSM116	1100	43.31	600	23.62
P2PPSM116G	1100	43.31	600	23.62
P2PPSM118	1100	43.31	800	31.50
P2PPSM118G	1100	43.31	800	31.50
P2PPSM1110	1100	43.31	1000	39.37
P2PPSM1110G	1100	43.31	1000	39.37

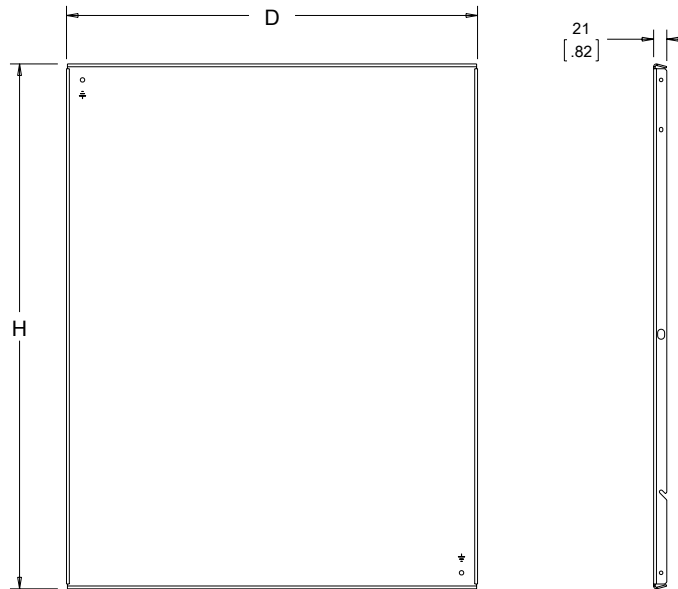

89129474

Notes