




# Specification High Power LED Shoe Box

## LED

50,000 Hours Life, 120 Watt, 120-277VAC 60Hz



### Applications:

Parking Lots, Security Lighting, Pole, Post Mount

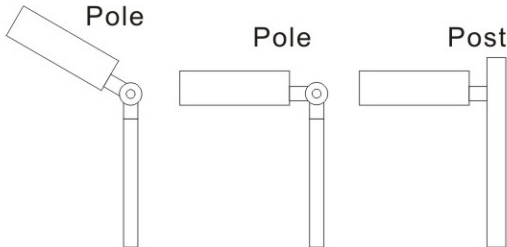

### Features:

- Replace 400W HID Unit
- 120/277 Dual Voltages
- Aluminum Rust Proof Body
- Instant Start Electronic Unit
- Suitable For Wet Location(IP65)
- Adjustable Multiple Mounting Methods (Pole Mount Includes)
- Not Dimmable

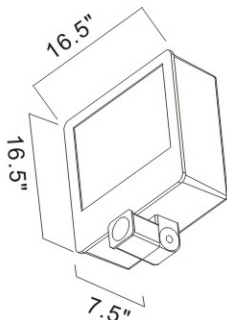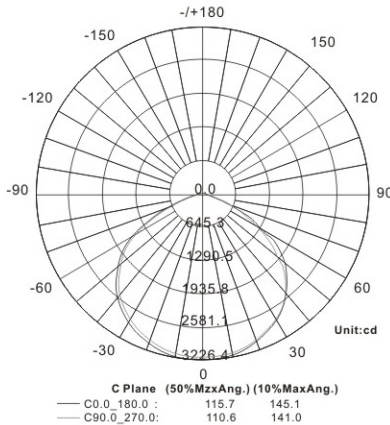

### WARRANTY

\* 5-YEAR

### Accessories Mounting Arms

Adjustable Pole  
Mounting Elbow  
(Included)



U-Bracket



Rectangular  
Post Arm



Catalog Number

Notes


Type



### Specification:

Input Line Voltage:	120-277VAC
Input Power	120W
Input Line Frequency	60Hz
Lamp Life (Rated)	50,000hrs
Minimum Starting Temp	-20°C/-4°F
Maximum Operating Temp	45°C/113°F
CCT	5000K
CRI	≥70
Lumens	11000
CBCP	3226

### Illuminance-Distance Diagram

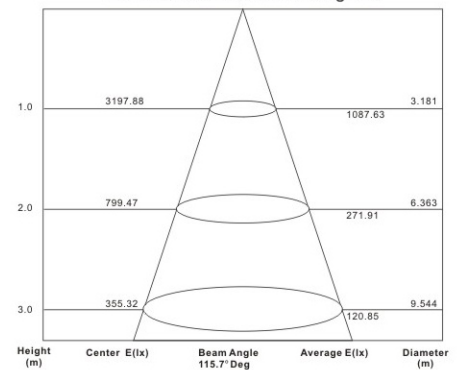

Note: The curves indicate the illuminated area and the average illumination when the luminaire is at different distance.

Model:#	Description	wattage	lumens
LWP120SBF/DL	120 Watt Hard Wire LED Light Bronze Color, Day Light	120W	11000

\*Based on 4hours usage a day  
"Accessories Sold Separately"

UPC: 680596-581604



Cyber Tech Lighting, Inc.  
1301 E Wilshire Ave, Santa Ana, CA 92705  
Tel: 714-543-8500, 1-877-60CYBER Fax: 714-543-8501  
www.cybertechlighting.com

