



Specification

63 Watt 8Ft LED Covered Strip Light Fixture

LED



50,000 Hours Life, 63 Watt, 120-277VAC 50/60Hz

Applications:

Garages, Carports, Walk Ways, Warehouse, Retail Stores
Restrooms, Commercial Buildings, Airplane Hangers, Laundry
Rooms, Freezers

Features:

- Ceiling Mount
- Operates On 120 to 277 Volts
- 0-10V Dimmable
- Steel Body.
- Easy Fit Polycarbonate Lens
- 50,000 Hours Life.
- 5 Year Limited Warranty

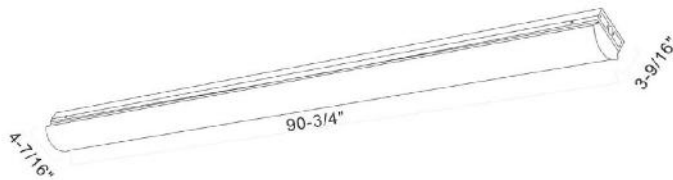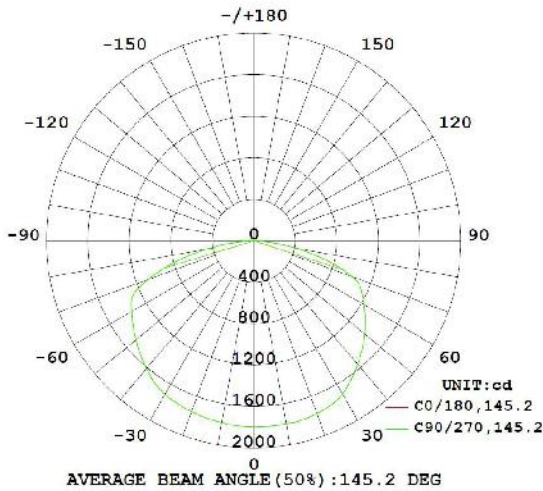

Catalog Number


Notes

Type



Specification:

Input Line Voltage.....	120-277VAC
Input Power.....	63W
Input Line Frequency	50/60Hz
Lamp Life (Rated)	50,000hrs
Minimum Starting Temp	-20°C/-4°F
Maximum Operating Temp	40°C/104 °F
CCT	4000K/5000
CRI	≥80
Lumens	7100
CBCP.....	1799
Dimmable	0-10V

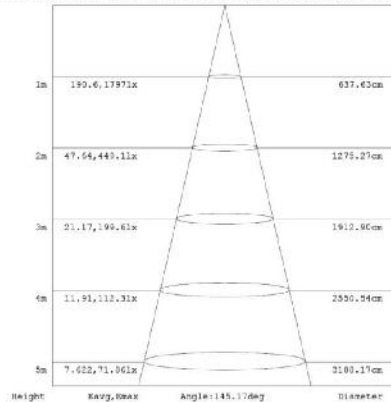

Note: The Curves indicate the illuminated area and the average illumination when the luminaire is at different distance.

WARRANTY

5-YEAR

Model:#	Description	wattage	lumens
ST9660L-LED/840	8 Ft Covered Strip Light Fixture, with Lens Cool White	63	7100
ST9660L-LED/850	8 Ft Covered Strip Light Fixture, with Lens Day Light	63	7100

* 5 Years Limited Warranty

UPC: ST9660L-LED/840 80680215395-7
ST9660L-LED/850 80680215394-0



Cyber Tech Lighting, Inc.
331 S. Hale Ave. Fullerton, CA 92831 USA.
Tel: 714-870-0794, 1-877-60CYBER Fax: 714-870-0795
www.cybertechlighting.com



ST3-1216